



SAW Traps

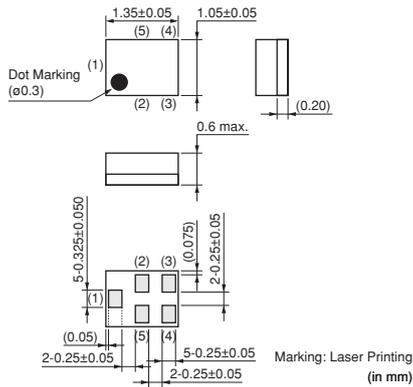

SAEEB Series

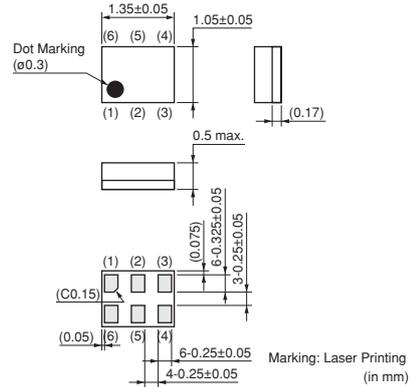

SAEEL Series

Part Number	Application	Center Frequency (MHz)	Att. BW (MHz)	I.L. 1 (dB max.)	I.L. 2 (dB max.)	I.L. 3 (dB max.)	Attenuation (dB min.)
SAEEL837MMA0F00	ISDB-T	837.5	830 to 845	1.0 (470 to 548MHz)	1.8 (548 to 710MHz)	4.1 (710 to 770MHz)	41 (830 to 845MHz)
SAEEL822MMA0F0A	ISDB-T	822.5	815 to 830	1.0 (470 to 548MHz)	1.7 (548 to 710MHz)	3.8 (710 to 770MHz)	40 (815 to 830MHz)
SAEEL832MVA0F55	ISDB-T	832/911.5	900 to 915	1.0 (470 to 548MHz)	1.5 (548 to 710MHz)	3.0 (710 to 770MHz)	38 (900 to 915MHz)
SAEEB897MBB0B00	DVB-H	897.5	880 to 915	2.0 (470 to 750MHz)	3.4 (750 to 798MHz)	-	41 (880 to 915MHz)