


EMI静音用铁氧体磁芯

磁珠芯

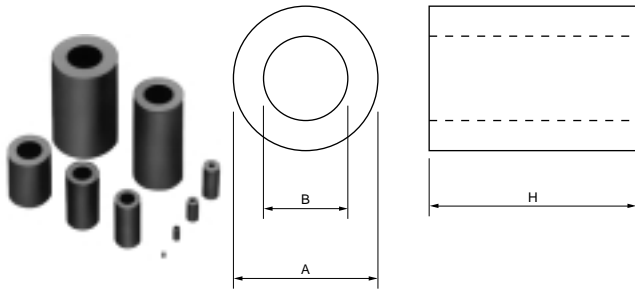


4

静音元件 / EMI静音滤波器

品名	Phi A: 外径尺寸 (mm)	Phi B: 内径尺寸 (mm)	H: 长度尺寸 (mm)	100MHz时的阻抗 (1旋转) (ohm)	注
FSRH021049RNB00B	1.95	1.02	4.9	34	-
FSRH030060RNB00B	3.36	1.1	6.0	74	-
FSRH041D85RNB00B	3.6	1.0	4.85	66	-
FSRH044C00RNB00B	3.6	1.5	3.0	40	-
FSRH044030RNA00B	3.7	1.4	3.1	40	Resin coat
FSRH044040RNB00B	3.6	1.5	4.0	50	-
FSRH044050RNB00B	3.6	1.5	5.0	53	-
FSRH050050RN000B	4.7	1.4	5.0	64	-
FSRH050100RN000B	4.7	1.4	10.0	120	-
FSRH060080RN000B	5.5	2.7	8.0	64	-
FSRH070080RN000B	7.0	4.0	8.0	59	-
FSRH070140RN000B	7.0	4.0	14.0	82	-
FSRH090100RN000B	9.0	5.0	10.0	72	For USB/IEEE1394
FSRH090160RN000B	9.0	5.0	16.0	100	For USB/IEEE1394
FSRH090200RN000T	9.0	5.0	20.0	135	For USB/IEEE1394
FSRH091100RN000B	9.0	4.3	10.0	94	For USB/IEEE1394
FSRH091160RN000T	9.0	4.3	16.0	145	For USB/IEEE1394
FSRH100150RTB00T	10.0	6.0	15.0	92	For USB/IEEE1394
FSRH120150RT000T	12.0	7.0	15.0	90	For USB/IEEE1394
FSRH120200RT000T	12.0	7.0	20.0	120	For USB/IEEE1394
FSRH120285RT000T	12.0	7.0	28.5	175	For USB/IEEE1394
FSRH121150RT000T	12.0	5.6	15.0	130	For USB/IEEE1394
FSRH121200RT000T	12.0	5.6	20.0	170	For USB/IEEE1394
FSRH121250RT000T	12.0	5.6	25.0	223	For USB/IEEE1394
FSRH142150RX000T	14.0	8.0	15.0	97	-
FSRH142200RX000T	14.0	8.0	20.0	127	-
FSRH142280RX000T	14.0	8.0	28.0	170	-
FSRH162200RN000T	16.3	8.3	20.0	162	-
FSRH162280RN000T	16.3	8.3	28.0	225	-
FSRH190285RT000T	19.0	10.0	28.5	200	-

EMI静噪用铁氧体磁芯

磁环芯

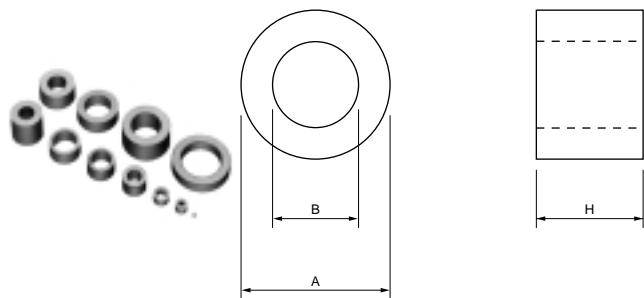


品名	Phi A: 外径尺寸 (mm)	Phi B: 内径尺寸 (mm)	H: 长度尺寸 (mm)	100MHz时的阻抗 (3旋转) (ohm)	注
FSRB060040RNB00B	5.5	2.7	4.0	290	-
FSRB071040RNB00B	7.0	4.0	4.0	222	-
FSRB090060RNB00B	9.0	5.0	6.0	356	For USB/IEEE1394
FSRB090080RNB00B	9.0	5.0	8.0	466	For USB/IEEE1394
FSRB091060RNB00B	9.0	4.3	6.0	451	For USB/IEEE1394
FSRB091080RNB00B	9.0	4.3	8.0	582	For USB/IEEE1394
FSRB100030RTB00B	10.0	6.0	3.0	170	For USB/IEEE1394
FSRB100060RTB00B	10.0	6.0	6.0	316	For USB/IEEE1394
FSRB100080RTB00B	10.0	6.0	8.0	388	For USB/IEEE1394
FSRB100100RTB00B	10.0	6.0	10.0	475	For USB/IEEE1394
FSRB120050RTB00T	12.0	7.0	5.0	264	For USB/IEEE1394
FSRB120060RTB00T	12.0	7.0	6.0	310	For USB/IEEE1394
FSRB120080RTB00T	12.0	7.0	8.0	400	For USB/IEEE1394
FSRB120100RTB00T	12.0	7.0	10.0	450	For USB/IEEE1394
FSRB121060RTB00T	12.0	5.6	6.0	406	For USB/IEEE1394
FSRB121080RTB00T	12.0	5.6	8.0	490	For USB/IEEE1394
FSRB121100RTB00T	12.0	5.6	10.0	535	For USB/IEEE1394
FSRB140080RNB00T	14.0	10.0	8.0	340	-
FSRB140140RNB00T	14.0	10.0	14.0	450	-
FSRB142060RXB00T	14.0	8.0	6.0	325	-
FSRB142080RXB00T	14.0	8.0	8.0	415	-
FSRB142100RXB00T	14.0	8.0	10.0	492	-
FSRB143140RNB00T	14.0	11.0	14.0	364	-
FSRB160G75RN000T	16.0	12.0	7.75	247	-
FSRB162030RNB00T	16.3	8.3	3.0	230	-
FSRB162050RN000T	16.3	8.3	5.0	310	-
FSRB162100RNB00T	16.3	8.3	10.0	557	-
FSRB162160RN000T	16.3	8.3	16.0	640	-
FSRB190060RTB00T	19.0	10.0	6.0	360	-
FSRB190100RT000T	19.0	10.0	10.0	480	-
FSRB190180RT000T	19.0	10.0	18.0	619	-
FSRB221080RNB00T	22.0	14.0	8.0	360	-
FSRB250120RT000T	25.0	15.0	12.0	470	-
FSRB300080RT000T	30.0	20.0	8.0	300	-

EMI静噪用铁氧体磁芯

用于扁平电缆

● 薄型

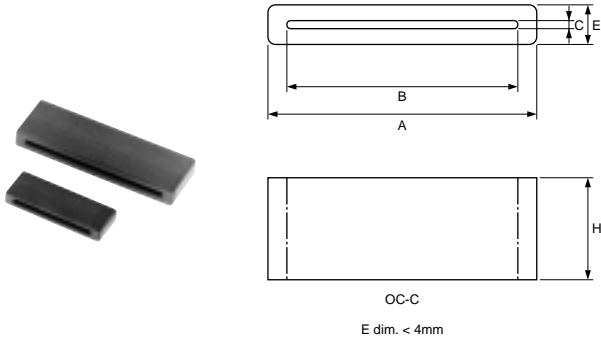

4

静噪元件 / EMI静噪滤波器


品名	A: 外径尺寸 (mm)	B: 内经尺寸 (mm)	H: 长度尺寸 (mm)	E: 宽度尺寸 (mm)	C: 间隙尺寸 (mm)	100MHz时的阻抗 (ohm)	旋转数	注
FSRC080030RTA00B	8.1	5.9	3.1	2.8	0.6	28	1	Thin Type, Resin coat
FSRC080030RTB00B	8.0	6.0	3.0	2.7	0.7	28	1	Thin Type
FSRC080060RTA00B	8.1	5.9	6.1	2.8	0.7	39	1	Thin Type, Resin coat
FSRC080060RTB00B	8.0	6.0	6.0	2.7	0.7	39	1	Thin Type
FSRC080090RTB00B	8.0	6.0	9.0	2.7	0.7	51	1	Thin Type
FSRC080120RTB00B	8.0	6.0	12.0	2.7	0.6	63	1	Thin Type
FSRC100030RTA00B	10.1	7.9	3.1	1.95	0.6	24	1	Ultra Thin Type, Resin coat
FSRC100030RTB00B	10.0	8.0	3.0	1.85	0.7	24	1	Ultra Thin Type
FSRC100040RTA00B	10.1	7.9	4.1	1.95	0.6	25	1	Ultra Thin Type, Resin coat
FSRC100040RTB00B	10.0	8.0	4.0	1.85	0.7	25	1	Ultra Thin Type
FSRC100050RTA00B	10.1	7.9	5.1	1.95	0.6	27	1	Ultra Thin Type, Resin coat
FSRC100050RTB00B	10.0	8.0	5.0	1.85	0.7	27	1	Ultra Thin Type
FSRC100060RTA00B	10.1	7.9	6.1	1.95	0.6	30	1	Ultra Thin Type, Resin coat
FSRC100060RTB00B	10.0	8.0	6.0	1.85	0.7	30	1	Ultra Thin Type
FSRC120020RXB00B	11.5	8.0	2.0	3.0	0.7	24	1	Thin Type
FSRC120050RXB00B	11.5	8.0	5.0	3.0	0.7	35	1	Thin Type
FSRC120060RXB00B	11.5	8.0	6.0	3.0	0.7	36	1	Thin Type
FSRC120090RXB00B	11.5	8.0	9.0	3.0	0.7	48	1	Thin Type
FSRC120120RXB00B	11.5	8.0	12.0	3.0	0.7	59	1	Thin Type
FSRC150030RTA00B	15.7	13.5	3.1	1.95	0.6	25	1	Ultra Thin Type, Resin coat
FSRC150030RTB00B	15.6	13.6	3.0	1.85	0.7	25	1	Ultra Thin Type
FSRC150040RTA00B	15.7	13.5	4.1	1.95	0.6	28	1	Ultra Thin Type, Resin coat
FSRC150040RTB00B	15.6	13.6	4.0	1.85	0.7	28	1	Ultra Thin Type
FSRC150050RTA00B	15.7	13.5	5.1	1.95	0.6	29	1	Ultra Thin Type, Resin coat
FSRC150050RTB00B	15.6	13.6	5.0	1.85	0.7	29	1	Ultra Thin Type
FSRC150060RTA00B	15.7	13.5	6.1	1.95	0.6	30	1	Ultra Thin Type, Resin coat
FSRC150060RTB00B	15.6	13.6	6.0	1.85	0.7	30	1	Ultra Thin Type
FSRC160040RTA00B	15.7	13.5	4.1	2.9	0.6	26	1	Thin Type, Resin coat
FSRC160040RTB00T	15.6	13.6	4.0	2.8	0.7	26	1	Thin Type
FSRC171030RTA00B	17.1	13.5	3.1	2.9	0.6	26	1	Thin Type, Resin coat
FSRC171030RTB00T	17.0	13.6	3.0	2.8	0.7	26	1	Thin Type
FSRC171060RTA00B	17.1	13.5	6.1	2.9	0.6	37	1	Thin Type, Resin coat
FSRC171060RTB00T	17.0	13.6	6.0	2.8	0.7	37	1	Thin Type
FSRC171090RTA00B	17.1	13.5	9.1	2.9	0.6	44	1	Thin Type, Resin coat
FSRC171090RTB00T	17.0	13.6	9.0	2.8	0.7	44	1	Thin Type
FSRC171120RTB00T	17.0	13.6	12.0	2.8	0.7	53	1	Thin Type
FSRC221150RTF10T	22.8	18.8	15.0	2.8	0.55	73	1	Thin Type, division type
FSRC222060RX000T	22.8	18.7	6.0	2.8	0.7	37	1	Thin Type
FSRC222090RX000T	22.8	18.7	9.0	2.8	0.7	46	1	Thin Type

接下页。

☐ 接上页。

品名	A: 外径尺寸 (mm)	B: 内经尺寸 (mm)	H: 长度尺寸 (mm)	E: 宽度尺寸 (mm)	C: 间隙尺寸 (mm)	100MHz时的阻抗 (ohm)	旋转数	注
FSRC222120RX000T	22.8	18.7	12.0	2.8	0.7	53	1	Thin Type
FSRC230060RTA00T	22.8	20.5	6.1	1.85	0.5	33	1	Ultra Thin Type, Resin coat
FSRC230060RTB00T	22.7	20.6	6.0	1.75	0.6	33	1	Ultra Thin Type
FSRC230090RTA00T	22.8	20.5	9.1	1.85	0.5	39	1	Ultra Thin Type, Resin coat
FSRC230090RTB00T	22.7	20.6	9.0	1.75	0.6	39	1	Ultra Thin Type
FSRC253060RT000T	25.0	21.0	6.0	3.0	0.8	41	1	Thin Type
FSRC253090RT000T	25.0	21.0	9.0	3.0	0.8	48	1	Thin Type
FSRC253120RT000T	25.0	21.0	12.0	3.0	0.8	56	1	Thin Type
FSRC280060RX000T	28.0	24.0	6.0	3.5	0.8	39	1	Thin Type
FSRC280090RX000T	28.0	24.0	9.0	3.5	0.8	46	1	Thin Type
FSRC280120RX000T	28.0	24.0	12.0	3.5	0.8	56	1	Thin Type
FSRC360060RX000T	36.0	32.0	6.0	3.5	0.8	40	1	Thin Type
FSRC360090RX000T	36.0	32.0	9.0	3.5	0.8	47	1	Thin Type
FSRC360120RX000T	36.0	32.0	12.0	3.5	0.8	56	1	Thin Type
FSRC420060RX000T	42.0	38.0	6.0	2.8	0.7	42	1	Thin Type
FSRC420090RX000T	42.0	38.0	9.0	2.8	0.7	48	1	Thin Type
FSRC420120RX000T	42.0	38.0	12.0	2.8	0.7	57	1	Thin Type

● 标准型

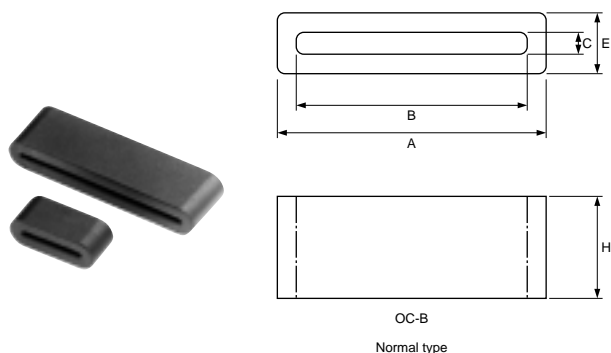

品名	A: 外径尺寸 (mm)	B: 内经尺寸 (mm)	H: 长度尺寸 (mm)	E: 宽度尺寸 (mm)	C: 间隙尺寸 (mm)	100MHz时的阻抗 (ohm)	旋转数	注
FSRC140030RXB00T	13.8	9.6	3.0	5.0	0.8	30	1	-
FSRC140040RXB00T	13.8	9.6	4.0	5.0	0.8	36	1	-
FSRC140060RXB00T	13.8	9.6	6.0	5.0	0.8	44	1	-
FSRC140090RXB00T	13.8	9.6	9.0	5.0	0.8	66	1	-
FSRC140120RX000T	13.8	9.6	12.0	5.0	0.8	78	1	-
FSRC140200RXB00T	13.8	9.6	20.0	5.0	0.8	126	1	-
FSRC141060RXB00T	13.8	10.8	6.0	5.0	1.3	39	1	-
FSRC141120RXB00T	13.8	10.8	12.0	5.0	1.3	62	1	-
FSRC170030RTB00T	17.0	13.0	3.0	5.0	0.8	26	1	-
FSRC170060RTB00T	17.0	13.0	6.0	5.0	0.8	37	1	-
FSRC170070RT000T	17.0	13.0	7.0	5.0	0.8	45	1	-
FSRC170090RTB00T	17.0	13.0	9.0	5.0	0.8	53	1	-
FSRC170120RT000T	17.0	13.0	12.0	5.0	0.8	75	1	-
FSRC170200RT000T	17.0	13.0	20.0	5.0	0.8	107	1	-
FSRC192060RTB00T	18.8	14.6	6.0	5.9	1.6	35	1	-
FSRC192090RTB00T	18.8	14.6	9.0	5.9	1.6	47	1	-
FSRC192120RTB00T	18.8	14.6	12.0	5.9	1.6	58	1	-
FSRC240150RX000T	23.8	18.8	15.0	6.3	1.1	76	1	-
FSRC250070RT000T	25.0	21.0	7.0	5.0	0.8	45	1	-
FSRC250120RT000T	25.0	21.0	12.0	5.0	0.8	70	1	-


☐ 接下页。

△注 本PDF产品目录是从株式会社村田制作所网站中下载的。规格若有变更，或若其中产品停产，恕不另行通知。请在订购之前向我公司销售代表或产品工程师查询。
 本PDF产品目录所记载的产品规格，因受篇幅的限制，只提供了主要产品资料。在您订购前，必须确认规格表内容，或者互换协商定案图。

☐ 接上页。

品名	A: 外径尺寸 (mm)	B: 内径尺寸 (mm)	H: 长度尺寸 (mm)	E: 宽度尺寸 (mm)	C: 间隙尺寸 (mm)	100MHz时的阻抗 (ohm)	旋转数	注
FSRC252050RT000T	25.0	21.0	5.0	5.0	1.2	35	1	-
FSRC252060RT000T	25.0	21.0	6.0	5.0	1.2	39	1	-
FSRC252090RT000T	25.0	21.0	9.0	5.0	1.2	47	1	-
FSRC252120RT000T	25.0	21.0	12.0	5.0	1.2	55	1	-
FSRC260060RT000T	26.0	22.0	6.0	5.0	1.2	38	1	-
FSRC260090RT000T	26.0	22.0	9.0	5.0	1.2	49	1	-
FSRC271113RN000T	27.0	22.25	11.3	8.05	2.15	55	1	-
FSRC310060RN000T	31.0	27.0	6.0	5.0	0.8	47	1	-
FSRC310090RN000T	31.0	27.0	9.0	5.0	0.8	58	1	-
FSRC310120RN000T	31.0	27.0	12.0	5.0	0.8	70	1	-
FSRC310200RN000T	31.0	27.0	20.0	5.0	0.8	102	1	-
FSRC320080RT000T	32.0	27.8	8.0	6.5	1.3	45	1	-
FSRC320120RT000T	32.0	27.8	12.0	6.5	1.3	60	1	-
FSRC400120RTF10T	40.0	35.0	12.0	4.0	0.5	80	1	division type
FSRC401120RT000T	40.0	35.0	12.0	4.5	1.0	65	1	-
FSRC410150RN000T	41.2	35.0	15.0	7.7	1.5	70	1	-
FSRC560120RT000T	56.2	52.2	12.0	4.8	0.9	70	1	-
FSRC580060RT000T	58.0	52.8	6.0	6.7	1.5	46	1	-
FSRC580120RT000T	58.0	52.8	12.0	6.7	1.5	62	1	-
FSRC581180RTF00T	58.0	52.8	18.0	6.2	1.0	95	1	division type
FSRC600100RN000T	60.0	48.0	10.0	12.0	1.9	69	1	-
FSRC600127RN000T	60.0	48.0	12.7	12.0	1.9	72	1	-
FSRC800127RTF30T	80.0	68.6	12.7	10.0	2.6	71	1	division type


● 厚型

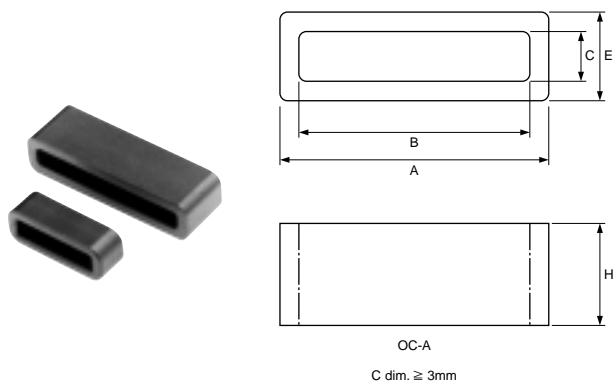


品名	A: 外径尺寸 (mm)	B: 内径尺寸 (mm)	H: 长度尺寸 (mm)	E: 宽度尺寸 (mm)	C: 间隙尺寸 (mm)	100MHz时的阻抗 (ohm)	旋转数	注
FSRC142150RTB00T	14.0	9.0	15.0	9.0	4.0	90	1	Wide Type
FSRC190060RTB00T	19.0	15.0	6.0	7.0	3.5	34	1	Wide Type
FSRC191085RT000T	19.0	13.0	8.5	18.0	12.0	44	1	for USB Connector (type B)
FSRC321100RN000T	32.0	28.0	10.0	7.5	3.5	35	1	Wide Type
FSRC321150RN000T	32.0	28.0	15.0	7.5	3.5	47	1	Wide Type
FSRC440100RN000T	44.0	40.0	10.0	7.5	3.8	34	1	Wide Type

EMI静噪用铁氧体磁芯

多孔磁芯

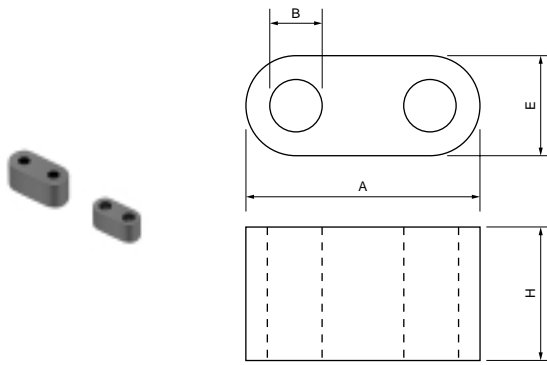

FSMA Type for Balun Transformer

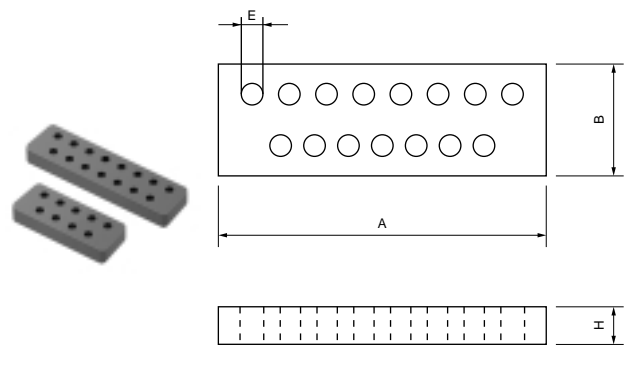


FSSA Type for Connector

品名	A: 外径尺寸 (mm)	B, E: 孔径尺寸 (mm)	H: 长度尺寸 (mm)	B, E: 宽度尺寸 (mm)	100MHz时的阻抗 (ohm)	注
FSMA050020RLB00B	5.20	1.30	2.00	2.50	21	-
FSMA050020RTB00B	5.20	1.30	2.00	2.50	20	-
FSMA072020RLB00B	6.50	1.10	2.00	3.00	23	-
FSSA160025RN000T	16.0	1.15	2.5	6.4	43	for connector
FSSA240025RN000T	24.0	1.15	2.5	6.4	45	for connector

EMI静噪用铁氧体磁芯

平面磁芯

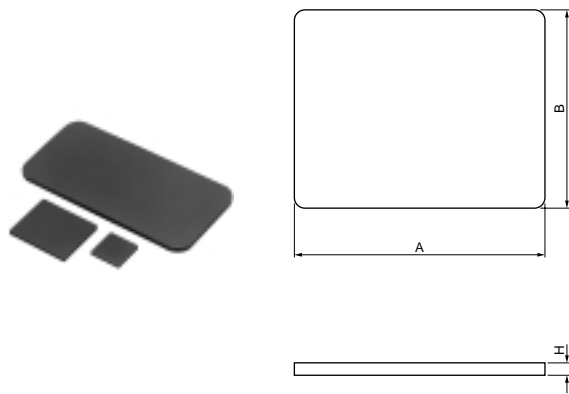

品名	A: 外径尺寸 (mm)	B: 宽度尺寸 (mm)	H: 厚度尺寸 (mm)	注
FSSA100008RN000T	10.0	10.0	0.8	-
FSSA100008RNA00T	10.1	10.1	0.9	Resin coat
FSSA100010RN000T	10.0	10.0	1.0	-
FSSA100010RNA00T	10.1	10.1	1.1	Resin coat
FSSA100Z55RN000T	10.0	10.0	0.55	-
FSSA100Z55RNA00T	10.1	10.1	0.65	Resin coat
FSSA101005RN000T	10.0	5.0	0.5	-
FSSA130004RN000T	13.0	5.0	0.4	-
FSSA130004RNA00T	13.1	5.1	0.5	Resin coat
FSSA150015RN000T	15.5	15.5	1.5	-
FSSA151005RN000T	15.0	5.0	0.5	-
FSSA190010RN000T	19.0	6.0	1.0	-
FSSA202010RN000T	20.0	16.5	1.0	-
FSSA202015RN000T	20.0	16.5	1.5	-

接下页。

△注 · 本PDF产品目录是从株式会社村田制作所网站中下载的。规格若有变更，或者其中产品停产，恕不另行通知。请在订购之前向我公司销售代表或产品工程师查询。
· 本PDF产品目录所记载的产品规格，因受篇幅的限制，只提供了主要产品资料。在您订购前，必须确认规格表内容，或者互换协商定案图。


☐ 接上页。

品名	A: 外径尺寸 (mm)	B: 宽度尺寸 (mm)	H: 厚度尺寸 (mm)	注
FSSA203005RN00T	20.0	20.0	0.5	-
FSSA203005RNA00T	20.1	20.1	0.6	Resin coat
FSSA203010RN00T	20.0	20.0	1.0	-
FSSA203010RNA00T	20.1	20.1	1.1	Resin coat
FSSA203015RN00T	20.0	20.0	0.5	-
FSSA222011RT00T	22.8	16.5	1.1	-
FSSA230008RN00T	23.0	23.0	0.8	-
FSSA230010RN00T	23.0	23.0	1.0	-
FSSA230015RN00T	23.0	23.0	1.5	-
FSSA250004RN00T	25.0	7.0	0.4	-
FSSA270010RN00T	27.0	20.0	1.0	-
FSSA271010RN00T	27.0	27.0	1.0	-
FSSA271020RN00T	27.0	27.0	2.0	-
FSSA271050RN00T	27.0	27.0	5.0	-
FSSA272010RN00T	27.0	15.0	1.0	-
FSSA290005RN00T	29.0	5.0	0.5	-
FSSA300010RN00T	30.0	30.0	1.0	-
FSSA401010RN00T	41.5	10.0	1.0	-
FSSA450015RT00T	45.0	10.0	1.5	-
FSSA530015RT00T	52.8	28.5	1.5	-
FSSA600020RN00T	60.5	30.6	2.0	-

4 静噪元件 / EMI静噪滤波器

EMI静噪用铁氧体磁芯

薄型夹层磁芯

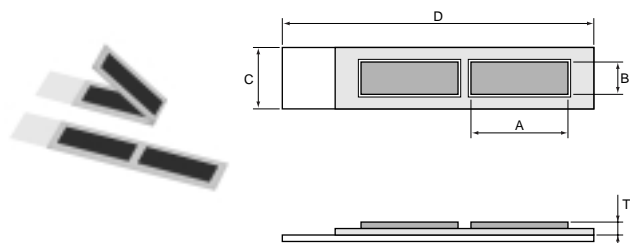

品名	A: 铁氧体磁芯外形尺寸 (mm)	B: 宽度尺寸 (mm)	T: 铁氧体磁芯厚度 (mm)	C: 粘附膜宽度 (mm)	D: 粘附膜长度 (mm)	100MHz时的阻抗 (ohm)	重量 (g)
FSSA101005RNN00S	10.0	5.0	0.5	9.5	35.0	28	0.28
FSSA101005RNN30S	10.0	5.0	0.5	9.5	35.0	28	0.28
FSSA151005RNN00S	15.0	5.0	0.5	9.5	45.0	28	0.43
FSSA151005RNN30S	15.0	5.0	0.5	9.5	45.0	28	0.43
FSSA205007RNN00S	20.0	7.0	0.7	13.5	55.0	34	0.98
FSSA205007RNN30S	20.0	7.0	0.7	13.5	55.0	34	0.98
FSSA220007RNN00S	22.0	7.0	0.7	11.5	59.0	35	1.17
FSSA220007RNN30S	22.0	7.0	0.7	11.5	59.0	35	1.17
FSSA290005RNN00S	29.0	5.0	0.5	9.5	73.0	29	0.79
FSSA290005RNN30S	29.0	5.0	0.5	9.5	73.0	29	0.79