



射频二极管开关

声表滤波器内置式SWITCHPLEXER®

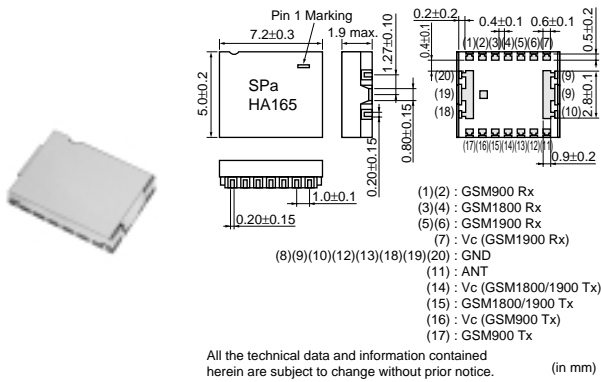

品名	频率范围 (Band1 Tx) (MHz)	频率范围 (Band1 Rx) (MHz)	频率范围 (Band2 Tx) (MHz)	频率范围 (Band2 Rx) (MHz)	频率范围 (Band3 Tx) (MHz)	频率范围 (Band3 Rx) (MHz)	插入损耗 (Band1 Tx-ANT) I) (dB)	插入损耗 (ANT-Band1 Rx) I) (dB)	插入损耗 (Band2 Tx-ANT) I) (dB)	插入损耗 (ANT-Band2 Rx) I) (dB)	插入损耗 (Band3 Tx-ANT) I) (dB)	插入损耗 (ANT-Band3 Rx) I) (dB)
LMS7CHA-165	f1: 897.5 ±17.5 MHz	942.5 ±17.5 MHz	fdth: 1747.5 ±37.5 MHz	fdrh: 1842.5 ±37.5 MHz	fpth: 1880.0 ±30.0 MHz	fprh: 1960.0 ±30.0 MHz	1.20 max. (at 25°C)	3.5 max. (at 25°C)	1.55 max. (at 25°C)	4.3 max. (at 25°C)	1.55 max. (at 25°C)	4.0 max. (at 25°C)

声表滤波器内置式三频分频器

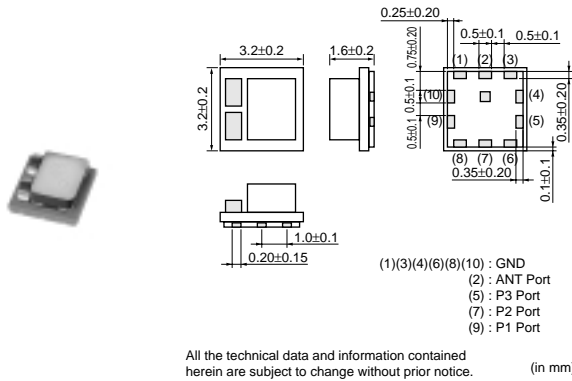

品名	频率范围 {P1}(f1) (MHz)	频率范围 {P2}(f2) (MHz)	频率范围 {P3}(f3) (MHz)	插入损耗 {ANT-P1}(in f1) I) (dB)	插入损耗 {ANT-P2Open}(in f2) III) (dB)	插入损耗 {ANT-P2}(in f2) I) (dB)	插入损耗 {ANT-P3}(in f3) I) (dB)
LMTP33AA-148	1575.50 ±1.5 MHz	859.0 ±35 MHz	1920.0 ±70.0 MHz	2.2 max. (at 25°C)	0.9 max. (at 25°C)	1.5 max. (at 25°C)	0.95 max. (at 25°C)

高频组件

9