

MURATA CMCC products application list and supported products








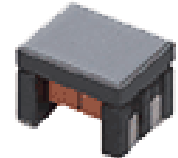
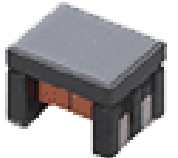
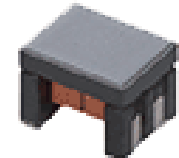
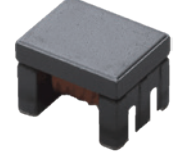

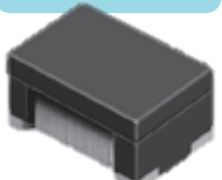
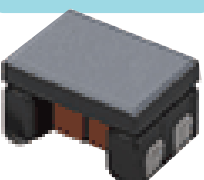
For Signal line - Automotive Grade -

Signal speed

Differential Signal

PoC*2

(inch/mm)

	CAN/ Flex Ray (-10Mbps)	CAN-FD (-8Mbps)		A2B® (50Mbps)	Ethernet 100Base-T1 (100Mbps)	USB 2.0 (480Mbps)	Ethernet 1000Base-T1 (1000Mbps)	LVDS <*1> (-1.5Gbps)	HDMI 1.4 (1.7Gbps)	HDMI 2.0 (6Gbps)	USB 3.1 (-10Gbps)	LVDS*1 (-6Gbps)	
		DCMR Class2	DCMR Class3										
1.25 x 1.0mm (0504/1210)						DLM11SN 101XT2 		DLM11SN _HZ2 Series 					
2.0 x 1.2mm (0805/2012)						DLW21SZ 900HQ2 		DLW21SZ Series 	DLW21SZ900HQ2 			NEW DLW21SH 391XQ2 DLW21PH 201XQ2	
3.2 x 2.5mm (1210/3225)	DLW32SH _XK2 Series 	DLW32SH 510XK2 DLW32SH 101XK2 	DLW32SH 101XF2 	DLW32MH 101XK2 	DLW32MH 201XK2 		DLW32MH 101XT2 						NEW 
4.5 x 3.2mm (1812/4532)	DLW43SH Series 				DLW43MH 201XK2 								

*1 : Ser Des *2 : Power over Coax