


# SCC1300-D04



## Appearance & Shape

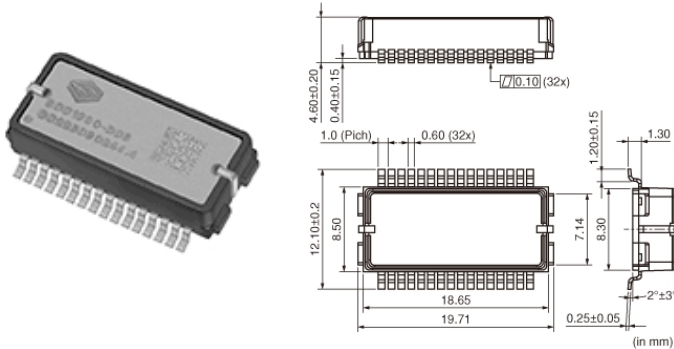

## Packaging Information

Packaging	Specifications	Standard Packing Quantity
-05	330mm Embossed Tape	50

**Attention**  
1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.  
2.This datasheet has only typical specifications because there is no space for detailed specifications.  
Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

# SCC1300-D04



## Specifications

Output Type	SPI
Supply Voltage	3.3&5.0V
Axis	3 / 1(X)
Mass	1.17g
Maximum Range	+/-6g,+/-300dps
Sensitivity	650 LSB/g,18 LSB/dps
Offset Temp. Characterisc	+/-40mg,+/-0.9dps
Amplitude Response	30...55Hz,50Hz

### Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2.This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.