


SCA100T-D02

To be discontinued

REACH

Appearance & Shape

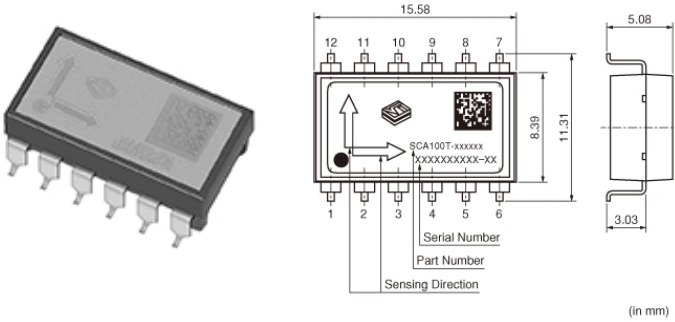

Packaging Information

Packaging	Specifications	Standard Packing Quantity
-1	330mm Embossed Tape	100

Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- 2.This datasheet has only typical specifications because there is no space for detailed specifications. Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

SCA100T-D02

Specifications

Output Type	Analog/SPI
Axis	2
Maximum Range	±1g ±90deg
Supply Voltage	5V
Offset Temp. Characteristic	±0.86deg
Sensitivity	2V/G
Amplitude Response	18Hz
Mass	1.01g

Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- 2.This datasheet has only typical specifications because there is no space for detailed specifications.
Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.