

# SCA620-EF8H1A


To be discontinued

AEC-Q100

RoHS

REACH

## Appearance & Shape

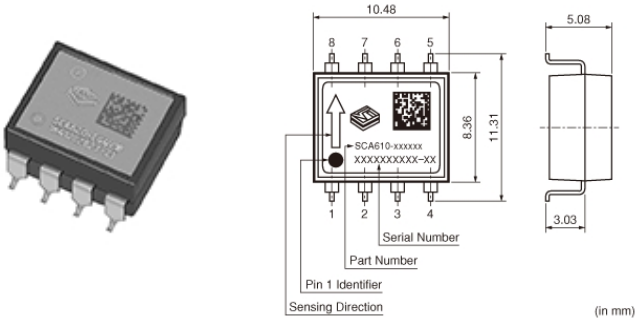

## Packaging Information

| Packaging | Specifications      | Standard Packing Quantity |
|-----------|---------------------|---------------------------|
| -1        | 330mm Embossed Tape | 100                       |

### Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- 2.This datasheet has only typical specifications because there is no space for detailed specifications.
- Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

# SCA620-EF8H1A



## Specifications

|                             |        |
|-----------------------------|--------|
| Output Type                 | Analog |
| Axis                        | 1(Z)   |
| Maximum Range               | ±1.7g  |
| Supply Voltage              | 5V     |
| Offset Temp. Characteristic | ±125mg |
| Sensitivity                 | 1.2V/G |
| Amplitude Response          | 50Hz   |
| Mass                        | 0.73g  |

### Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2.This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.