


SCA100T-D07

Discontinued

AEC-Q100

REACH

Appearance & Shape

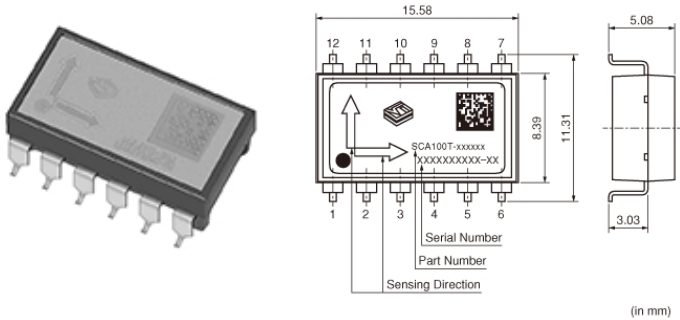

Packaging Information

Packaging	Specifications	Standard Packing Quantity
-1	330mm Embossed Tape	100

Attention
1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
2.This datasheet has only typical specifications because there is no space for detailed specifications.
Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

SCA100T-D07



Specifications

Output Type	Analog/SPI
Axis	2
Maximum Range	±12g
Supply Voltage	5V
Offset Temp. Characteristic	±300mg
Sensitivity	0.17V/G
Amplitude Response	400Hz
Mass	1.01g

Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2.This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.