


Test Circuit for Sound Pressure Level

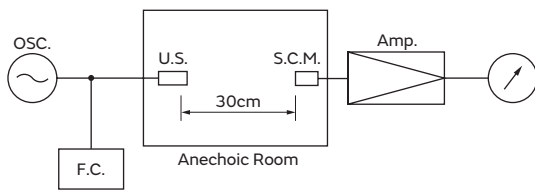

U.S. : Ultrasonic Sensor
S.C.M. : Standard Capacitor Microphone (Brüel&Kjær 4135)
Amp. : Amplifier (Brüel&Kjær 2610)
Input Voltage: 10 Vrms
F.C. : Frequency Counter