


酸化銀電池

Silver oxide batteries

SR43

■外形寸法 Dimensions(mm)

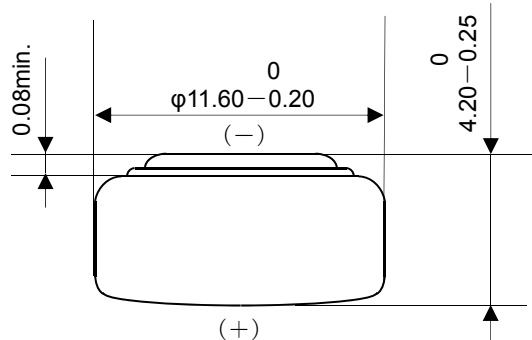

■刻印 Monogram




■定格 Specifications

公称電圧 Nominal Voltage	1.55 V
公称容量 (終止電圧 1.2V) Nominal Capacity (1.2V cutoff)	110 mAh
標準放電負荷 Standard Discharge Load ※公称電圧/抵抗 Nominal Voltage/Standard Load	6.8 k Ω (\approx 0.2mA)
標準質量 Weight	1.8 g
使用温度範囲 Operating Temperature	-10 ~ +60°C
用途 Applications	
<ul style="list-style-type: none"> ● 医療機器 ● 電子体温計 ● 玩具 ● 電卓 ● タイマー ● Medical Device ● Electric thermometers ● Toy ● Calculator ● Timer 	
水銀使用率 0% No mercury added	


■放電特性 Discharge Characteristics

load : 6.8k Ω temperature: 23°C

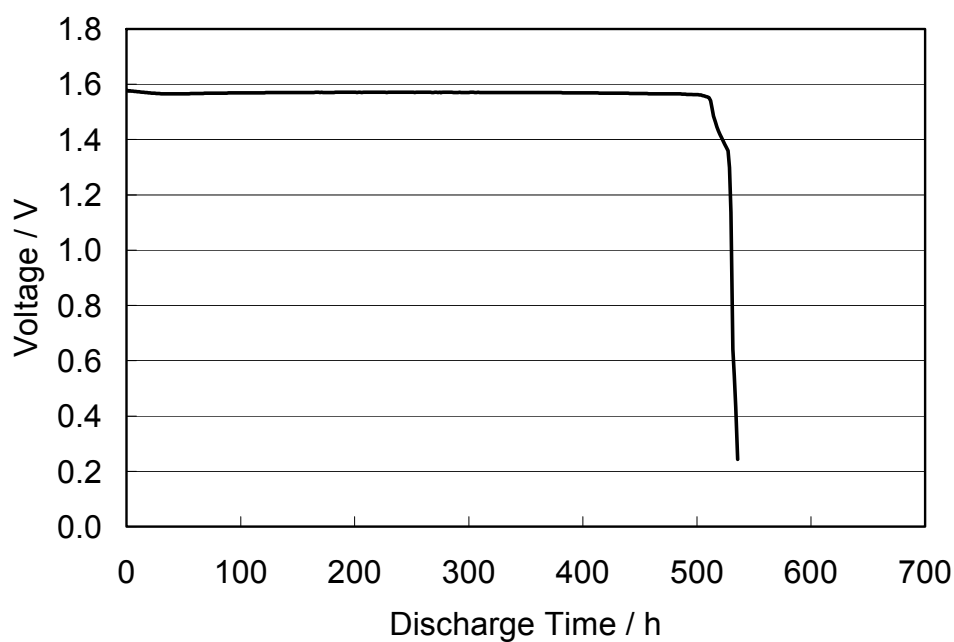


■ 放電負荷特性

Discharge Characteristics on Load

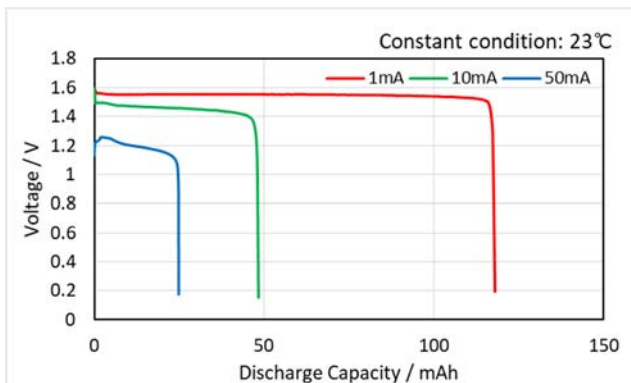


■ 放電温度特性

Discharge Characteristics by Temperature

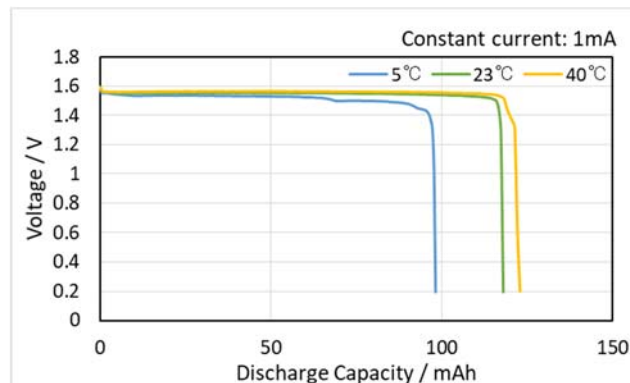

■ 放電負荷と放電容量

Discharge Load vs. Discharge Capacity

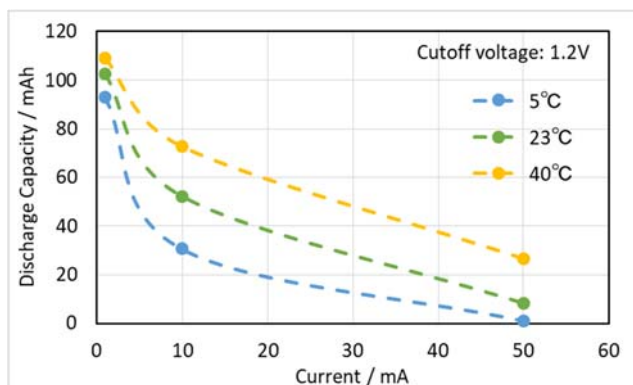

*記載のデータ及び数値は、参考値であり保証値ではありません。

*Data is not guaranteed, and is provided for reference purposes only.