



# PVM4A503C01B00

已经停产

RoHS

REACH

## 外观&形状

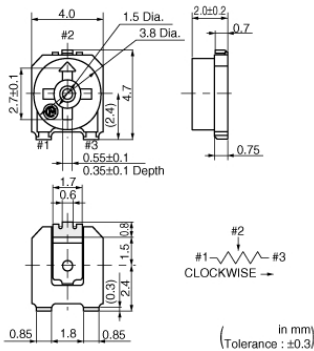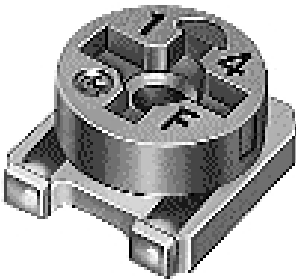

## 特点

1. Sealed construction protects the interior from dust and liquid, which achieves stable performance.
2. Available for flow and reflow soldering methods while maintaining unique sealed construction.
3. Simple construction of 3-piece parts achieves high reliability.
4. Large diameter slot of rotor improves driver insertion.
5. Available for cleaning after soldering.

## 包装信息

| 包装  | 规格  | 标准包装数量 |
|-----|-----|--------|
| B00 | 散装袋 | 500    |

注意

1. 本目录是从株式会社村田制作所网站中下载的。规格若有变更，或若其中产品停产，请在订购时确认，恕不另行通知。

2. 本目录因没有足够的空间说明详细规格，仅载明标准规格。因此，在订购产品之前，谨请核准其规格或者办理产品规格表。

# PVM4A503C01B00



规格


|              |                                           |
|--------------|-------------------------------------------|
| 额定功率         | 0.1W                                      |
| 形状           | SMD                                       |
| 最大工作电压       | 50Vdc                                     |
| 调整方向         | 上方                                        |
| 尺寸           | 4mm                                       |
| 自动调整         | Yes                                       |
| 调节转数(有效旋转角度) | 1(240°±10°)                               |
| 机械旋转角度       | Endless                                   |
| 总电阻值         | 50kΩ                                      |
| 总电阻值公差       | ±25%                                      |
| 电阻温度系数       | ±250ppm/°C                                |
| 电阻变化特性       | B (Linear)                                |
| 接触电阻变化       | 3% max. of nominal total resistance value |
| 剩余电阻         | 2% max. of nominal total resistance value |
| 焊接方法         | 温度曲线(回流),烙铁                               |
| 力矩           | 2.0 to 24.5mN · m                         |
| 额定功率测量条件     | 70°C                                      |
| 工作温度范围       | -55°C to 125°C                            |
| 质量           | 0.08g                                     |

**注意**  
1. 本目录是从株式会社村田制作所网站中下载的。规格若有变更，或若其中产品停产，请在订购时确认，恕不另行通知。  
2. 本目录因没有足够的空间说明详细规格，仅载明标准规格。因此，在订购产品之前，谨请核准其规格或者办理产品规格表。

# PVM4A503C01B00



## 产品数据

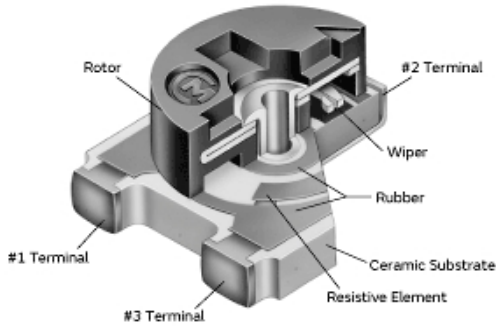

### 结构

在3 / 3页

#### 注意

1. 本目录是从株式会社村田制作所网站中下载的。规格若有变更，或若其中产品停产，请在订购时确认，恕不另行通知。
2. 本目录因没有足够的空间说明详细规格，仅载明标准规格。因此，在订购产品之前，请核准其规格或者办理产品规格表。