



# PVZ2A471C04B00

已经停产

RoHS

REACH

## 外观&形状

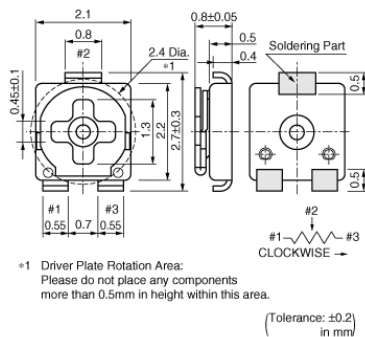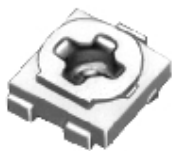

## 特点

1. Ultra-small and thin external dimensions of 2.1(W)x2.7(L)x0.85 max. (T)mm. (Top adjustment type: PVZ2A\_C04 Series)
2. Au plated termination achieves a high-density PCB mounting.
3. Cross-shaped driver slot allows for in-process automatic adjustment and it provides superior adjustability.
4. Two-piece parts construction achieves low cost and excellent quality.

## 包装信息

| 包装  | 规格  | 标准包装数量 |
|-----|-----|--------|
| B00 | 散装袋 | 1000   |

### 注意

1. 本目录是从株式会社村田制作所网站中下载的。规格若有变更，或若其中产品停产，请在订购时确认，恕不另行通知。
2. 本目录因没有足够的空间说明详细规格，仅载明标准规格。因此，在订购产品之前，谨请核准其规格或者办理产品规格表。

# PVZ2A471C04B00

规格

|              |                                           |
|--------------|-------------------------------------------|
| 额定功率         | 0.05W                                     |
| 形状           | SMD                                       |
| 最大工作电压       | 50Vdc                                     |
| 调整方向         | 上方                                        |
| 尺寸           | 2mm                                       |
| 自动调整         | Yes                                       |
| 调节转数(有效旋转角度) | 1(240°±10°)                               |
| 机械旋转角度       | Endless                                   |
| 总电阻值         | 470Ω                                      |
| 总电阻值公差       | ±30%                                      |
| 电阻温度系数       | ±500ppm/°C                                |
| 电阻变化特性       | B (Linear)                                |
| 接触电阻变化       | 5% max. of nominal total resistance value |
| 剩余电阻         | 2% max. of nominal total resistance value |
| 力矩           | 1.0 to 9.8mN · m                          |
| 额定功率测量条件     | 50°C                                      |
| 工作温度范围       | -25°C to 85°C                             |
| 质量           | 0.01g                                     |


注意

1. 本目录是从株式会社村田制作所网站中下载的。规格若有变更，或若其中产品停产，请在订购时确认，恕不另行通知。

2. 本目录因没有足够的空间说明详细规格，仅载明标准规格。因此，在订购产品之前， 谨请核准其规格或者办理产品规格表。

# PVZ2A471C04B00

## 产品数据

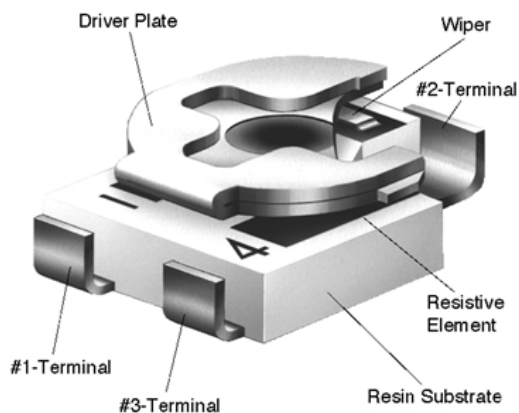

结构

### 注意

1. 本目录是从株式会社村田制作所网站中下载的。规格若有变更，或若其中产品停产，请在订购时确认，恕不另行通知。
2. 本目录因没有足够的空间说明详细规格，仅载明标准规格。因此，在订购产品之前，谨请核准其规格或者办理产品规格表。