


SV02C103BJZB1B01

已经停产

RoHS

REACH

外观&形状

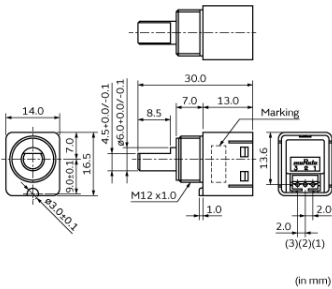

特点

1. High Durability :1000k cycles
2. Operating Temperature:-20 deg.C to +85 deg.C
3. SV02C is fixed by a nut on sheet metal, not by soldering.
4. Easy connection by a shaft structure, and by a connector for out-put voltage.
5. RoHS Compliant.
6. Special out-put curve is available.

■Applications

1. Switch for White goods
2. Pachinko steering wheel
3. Robot
4. Switch for Industrial equipment
5. Motor drive unit

包装信息

包装	规格	标准包装数量
B01	散装袋	750

注意

1. 本目录是从株式会社村田制作所网站中下载的。规格若有变更，或若其中产品停产，请在订购时确认，恕不另行通知。
2. 本目录因没有足够的空间说明详细规格，仅载明标准规格。因此，在订购产品之前，谨请核准其规格或者办理产品规格表。

SV02C103BJZB1B01

规格

工作温度范围	-20°C to 85°C
形状	连接器
总电阻值	10kΩ
总电阻值公差	±30%
线性	±3%
有效旋转角度(标准值)	280°
电阻温度系数	-
旋转寿命(max.)	1M cycles
力矩(max.)	4mN·m (Ref.:40gf.cm)
额定电压	5Vdc
耐电压	250Vac, 1 min., Leakage current 50 micro A max.
绝缘电阻(min.)	100MΩ
绝缘电阻测量条件	250Vdc
质量	5g


注意

1. 本目录是从株式会社村田制作所网站中下载的。规格若有变更，或若其中产品停产，请在订购时确认，恕不另行通知。

2. 本目录因没有足够的空间说明详细规格，仅载明标准规格。因此，在订购产品之前，谨请核准其规格或者办理产品规格表。

SV02C103BJZB1B01

产品数据

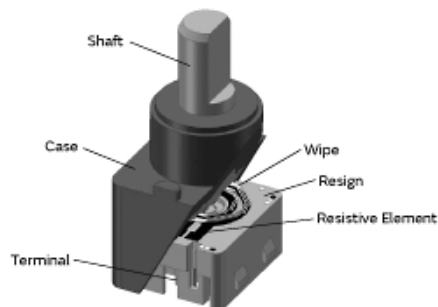

结构

在3 / 3页

注意

1. 本目录是从株式会社村田制作所网站中下载的。规格若有变更，或若其中产品停产，请在订购时确认，恕不另行通知。
2. 本目录因没有足够的空间说明详细规格，仅载明标准规格。因此，在订购产品之前，谨请核准其规格或者办理产品规格表。