 
 
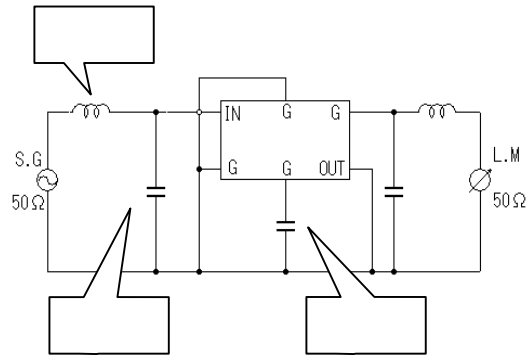
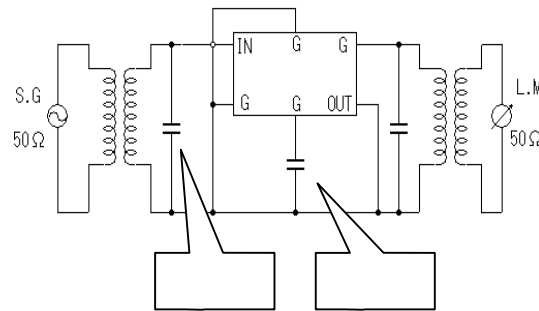


Check sheet for Crystal Filters (MCF) 1

Part number	
Customer name (End user name)	
Application	
MP (PP/pcs)	
Demand	
*size	3.8 x 3.8mm or 7.0 x 5.0mm
*Center frequency	[] MHz
*(1 or 3dB) Pass bandwidth	[] kHz Min., @3dB or @1dB
*Stop bandwidth	[] kHz Max., @[] dB
*Attenuation / Pole number	[] dB Min., @[] kHz/ [] Pole
Operating temp. range	-[] °C to +[] °C
Ripple	[] dB Max.
Insertion loss	[] dB Max.
IM characteristics	
Spurious	
Group delay	
Any other specification	
Comment	

Check sheet for Crystal Filters (MCF) 2

Termination impedance Type of the circuit	[] Ω // [] pF C_c = [] pF	
	☐ R • C matching circuit  ☐ C • L matching circuit 	☐ L • C matching circuit  ☐ Trans matching circuit 
Comment		