


Packaging specification/包装仕様

Type	Model name	Package (Ship mode)	Tray QTY (pcs)	Shrink/Sleeve pack QTY (pcs)	Master Carton QTY (pcs)	Package drawing	Battery orientation (Upward side)	Size L master carton (mm)	Size H master carton (mm)	Size W master carton (mm)	Master carton G Weight (kg)	
Standard	CR1216	Air & Boat	50	500	2000	Package 1	Anode	342	150	186	2.3	
	CR1220	Air & Boat	50	500	2000	Package 1	Anode	342	150	186	2.5	
	CR1616	Air & Boat	25	300	1200	Package 1	Anode	342	150	186	2.4	
	CR1620	Air & Boat	25	300	1200	Package 1	Anode	342	150	186	2.6	
	CR1632	Air & Boat	25	300	1200	Package 1	Anode	342	150	186	3.3	
	CR2016	Air & Boat	25	600	1200	Package 1	Anode	342	151	183	3.2	
	CR2025	Air & Boat	25	350	700	Package 1	Anode	342	151	183	2.6	
		Boat	25	350	1400	Package 2	Anode	342	151	183	4.8	
	CR2032	Air & Boat	25	350	700	Package 1	Anode	342	151	183	3.0	
		Boat	25	350	1400	Package 2	Anode	342	151	183	5.4	
	CR2430	Air & Boat	25	250	500	Package 1	Anode	342	151	183	2.9	
		Boat	25	250	1500	Package 2	Anode	342	151	183	7.8	
CR2450	Air & Boat	25	150	300	Package 1	Anode	342	151	183	2.6		
	Boat	25	150	900	Package 2	Anode	342	151	183	6.8		
Extended Temp.	CR2032X	Air & Boat	25	350	700	Package 1	Anode	342	150	186	2.9	
		Boat	25	350	1400	Package 2	Anode	342	150	186	5.2	
	CR2450X	Air & Boat	25	150	300	Package 1	Anode	342	150	186	2.4	
		Boat	25	150	900	Package 2	Anode	342	150	186	6.4	
	CR2477X	Air & Boat	25	100	200	Package 1	Anode	342	150	186	2.5	
		Boat	25	100	600	Package 2	Anode	342	150	186	6.4	
	CR3677X	Air & Boat	10	60	120	※	Anode	342	150	186	3.2	
		Boat	10	120	240	※	Anode	342	150	186	5.7	
Heat-resitant	CR2032W	Air & Boat	25	350	700	Package 1	Anode	342	150	186	3.0	
	CR2050W	Air & Boat	25	250	500	Package 1	Anode	342	150	186	2.8	
	CR2450W	Air & Boat	25	150	300	Package 1	Anode	342	150	186	2.6	
	CR2477W	Air & Boat	25	100	200	Package 1	Anode	342	150	186	2.8	
High Drain	CR2032R	Air & Boat	25	350	700	Package 1	Anode	342	150	186	2.9	
		Boat	25	350	1400	Package 2	Anode	342	150	186	5.2	
	CR2450R	Air & Boat	25	150	300	Package 1	Anode	342	150	186	2.4	
		Boat	25	150	900	Package 2	Anode	342	150	186	6.2	
Tab-welder	Standard	CR2032-HE1	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	1.6
		CR2032-HE8	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	1.6
		CR2032-HO6	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	1.6
		CR2032-VE3	Air & Boat	25	125	250	Package 3	Anode	363	152	187	1.6
		CR2430-HE1	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	1.9
		CR2430-HE2	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	1.9
		CR2430-HO1	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	1.9
		CR2430-VE1	Air & Boat	20	100	200	Package 3	Anode	363	152	187	1.7
		CR2450-HE5	Air & Boat	20	100	200	Package 4	Cathode	381	218	196	2.3
		CR2450-HE6	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	2.5
	Extended Temp.	CR2450-HO5	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	2.5
		CR2450-VE6	Air & Boat	20	100	200	Package 3	Anode	363	152	187	2.2
		CR2032X-HE1	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	1.6
		CR2032X-HO6	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	1.6
		CR2450X-HE6	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	2.4
		CR2450X-HO5	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	2.4
	Heat-resitant	CR2477X-HE2	Air & Boat	25	125	125	Package 4	Cathode	363	152	187	1.9
		CR2477X-HO4	Air & Boat	25	125	125	Package 4	Cathode	363	152	187	1.9
		CR2032W-HE1	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	1.6
		CR2032W-HO6	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	1.6
		CR2050W-MP6	Air & Boat	25	200	400	Package 3	Cathode	381	155	196	2.6
		CR2450W-HE6	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	2.5
		CR2450W-HO5	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	2.5
		CR2450W-MP1	Air & Boat	25	250	250	Package 4	Cathode	381	155	196	2.5
	High Drain	CR2477W-HE2	Air & Boat	25	125	125	Package 4	Cathode	363	152	187	2.0
		CR2477W-HO4	Air & Boat	25	125	125	Package 4	Cathode	363	152	187	2.0
		CR2032R-HE1	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	1.6
		CR2032R-HO6	Air & Boat	25	125	250	Package 3	Cathode	363	152	187	1.6
CR2450R-HE6		Air & Boat	25	125	250	Package 3	Cathode	363	152	187	2.4	
CR2450R-HO5		Air & Boat	25	125	250	Package 3	Cathode	363	152	187	2.3	

※CR3677Xの包装仕様図は別途お問い合わせください。


シュリンクパック

Shrink Pack

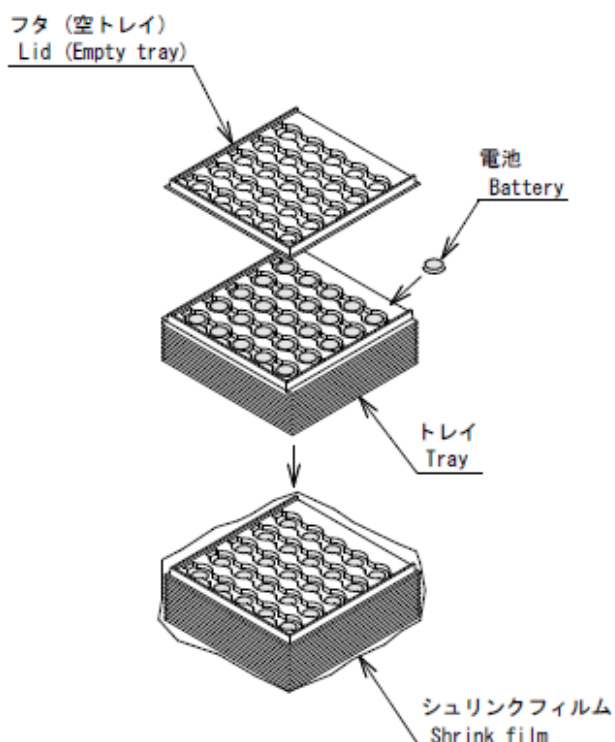


マスターカートン梱包

Master Box Packaging

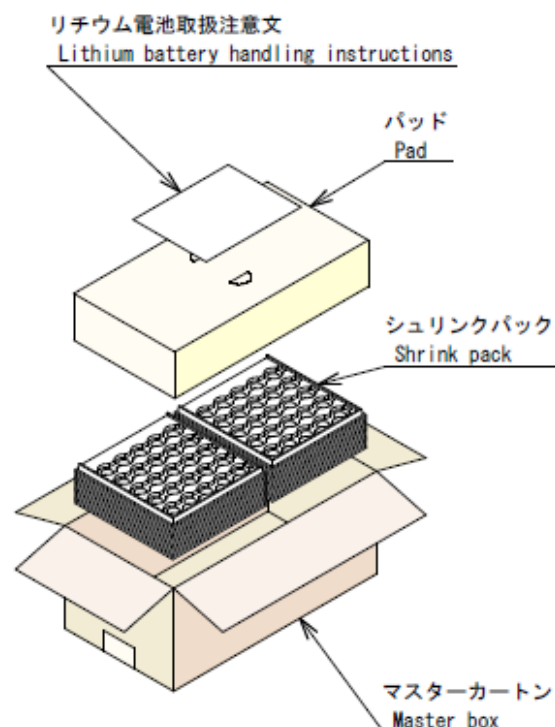


マスターカートン表示

Master Box Indication

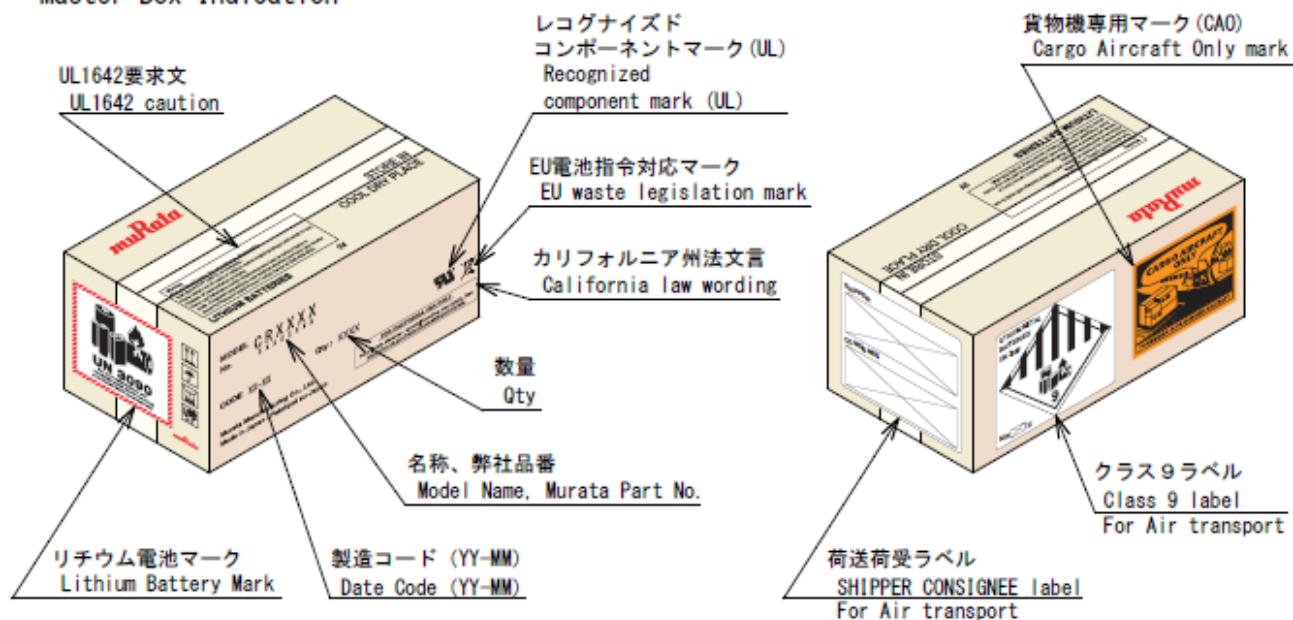


シュリンクパック

Shrink Pack

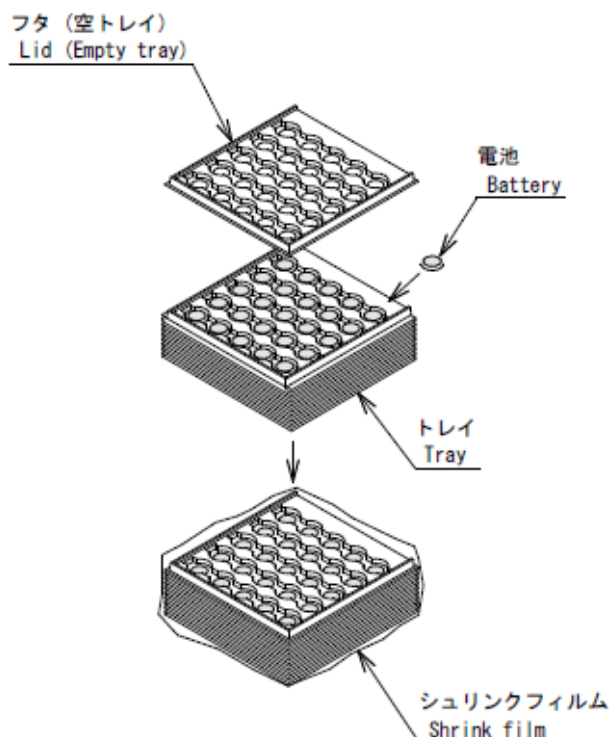


マスターカートン梱包

Master Box Packaging

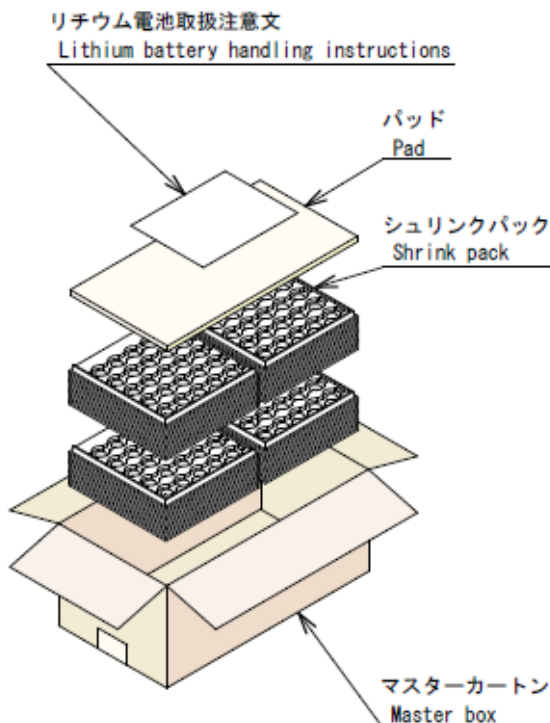


マスターカートン表示

Master Box Indication

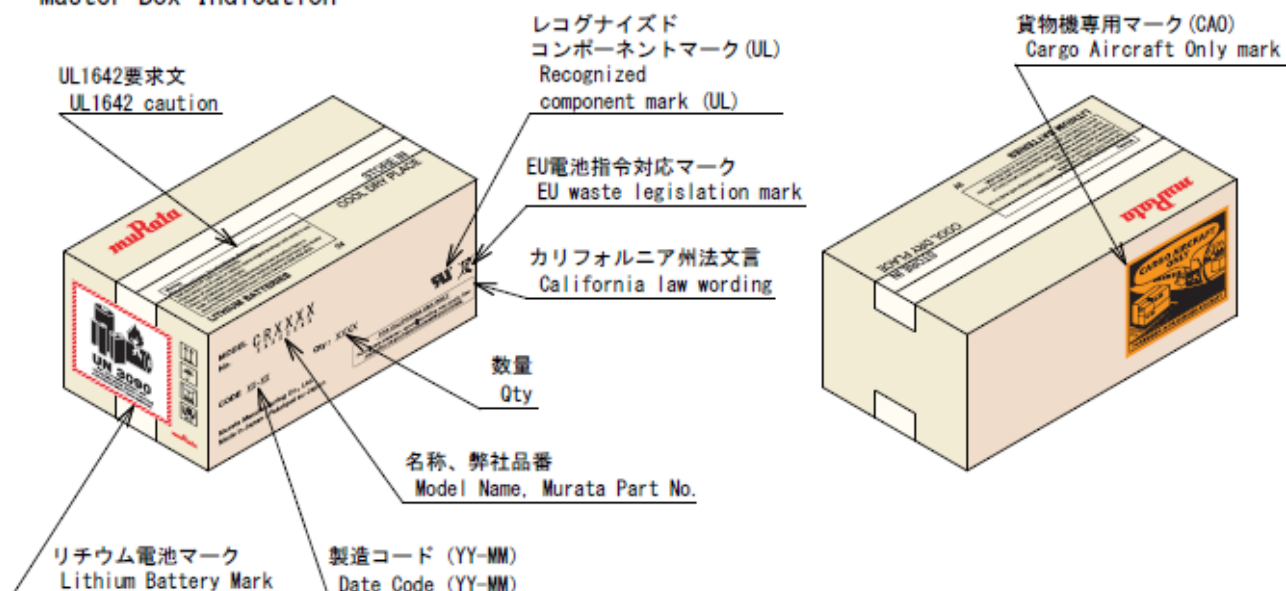


スリーブパック

Sleeve Pack

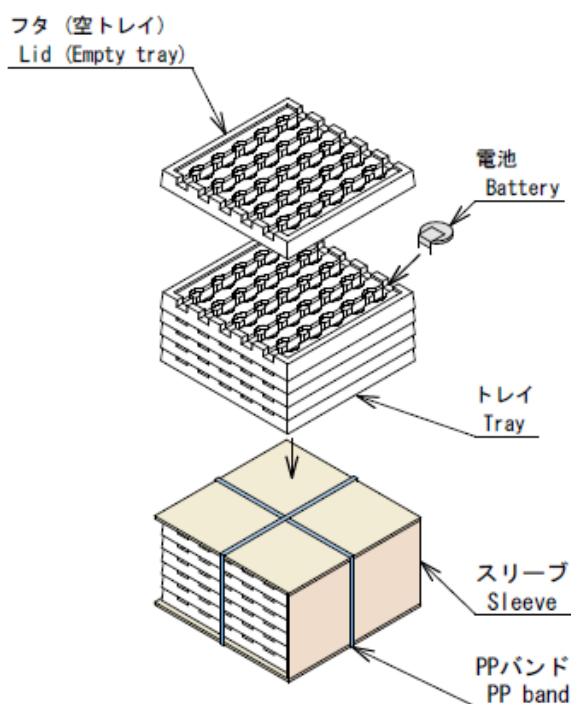


マスターカートン梱包

Master Box Packaging

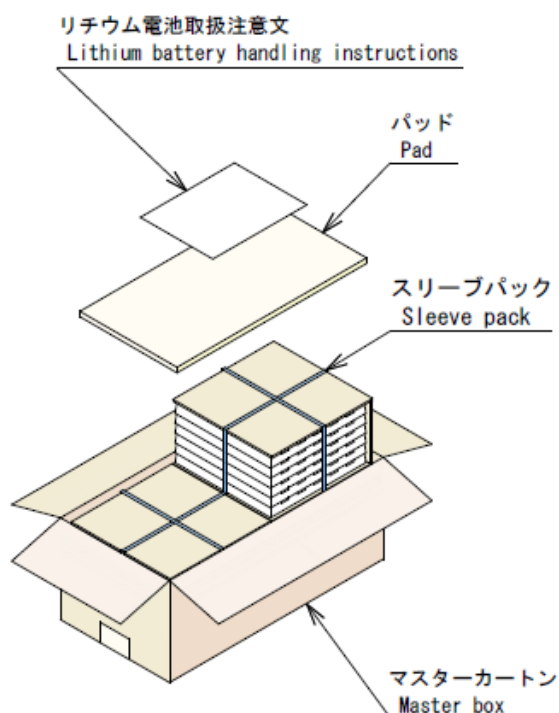


マスターカートン表示

Master Box Indication

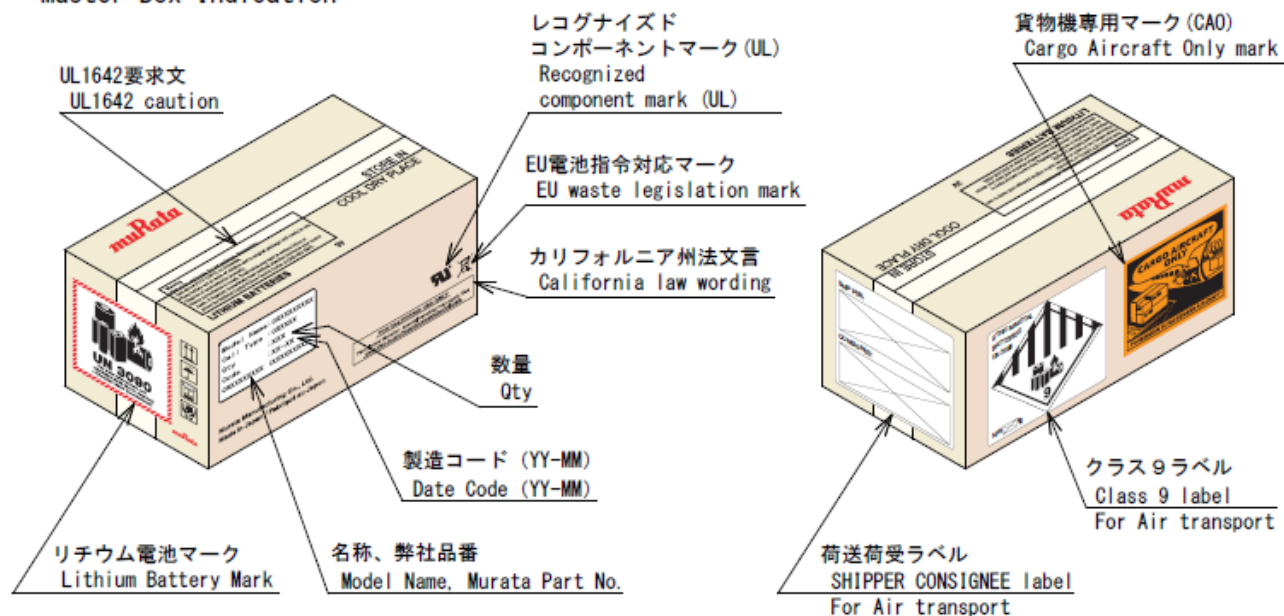


スリーブパック

Sleeve Pack

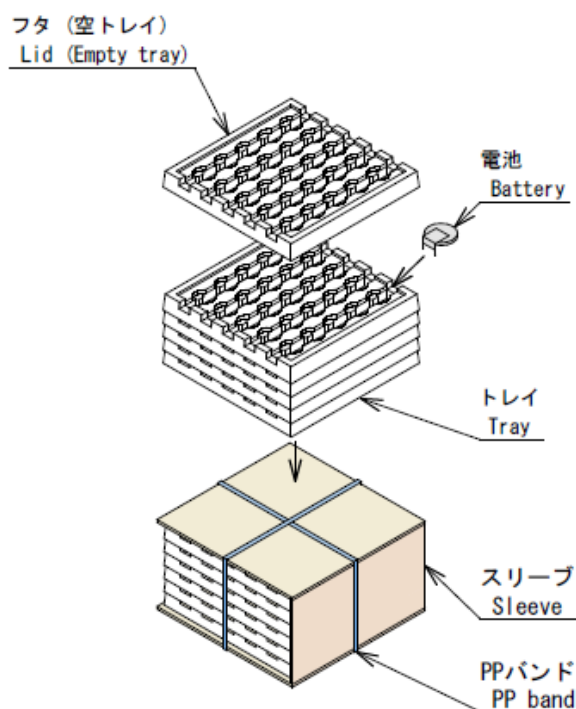

マスターカートン梱包

Master Box Packaging

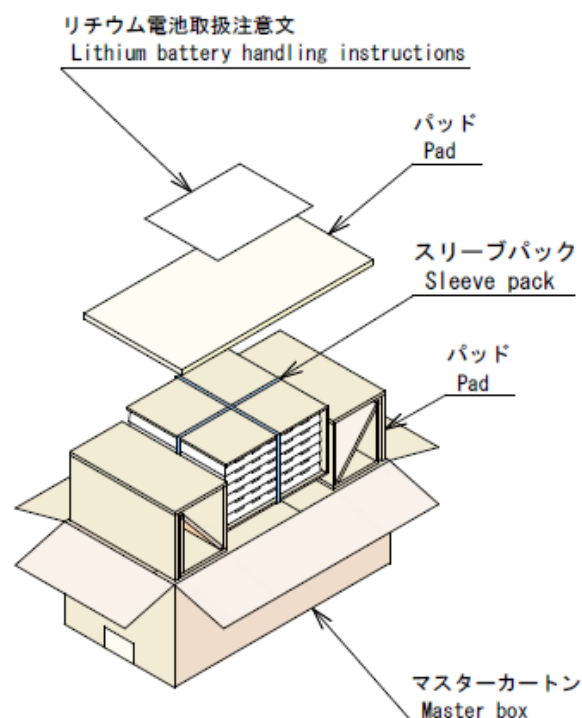

マスターカートン表示

Master Box Indication

